

Now for a limited time we are offering our valued

Nicolet 380 FTIR Spectrometer owners

special pricing on the purchase of the Nicolet iS10 FTIR Spectrometer!

Whether you're discovering new materials, solving analytical problems or assuring product quality, your spectrometer needs to deliver the definitive answers you're looking for – fast! Thermo Fisher Scientific goes beyond your expectations to help you move from sample to answer faster than ever before.

Advantages of the Thermo Scientific™ Nicolet™iS™10 FTIR Spectrometer

- **Faster analysis:** Results in half the time!
- **More reliable:** Continuous performance verification.
- **Seamless transition:** Use existing accessories, data, libraries, and macros.




Got this?



Get this and save over 20%

Feature	Nicolet 380	Nicolet iS10	Benefit
Signal-to-noise	15,000:1	50,000:1	Higher sensitivity and speed of analysis
Standard Spectral Resolution (cm-1)	0.8	0.4	Better peak shape and higher performance
Performance Verification/System Suitability	No	Yes	Address regulatory requirements and ensure consistent operation
NIST-traceable standards wheel included	No	Yes	Ensure test acceptance by QA and regulatory bodies
QCheck spectral correlation	No	Yes	Accurate and sensitive material inspection
OMNIC spectra material characterization	No	Yes	Mixture and contaminant identification, simplified data management
Set of libraries with over 22,000 spectra	No	Yes	Identify polymers, forensic materials and general chemicals
Desiccant efficiency	Standard	High Capacity	Ensure consistent spectral quality
Key component extended warranty	No	Yes	Reduces expensive part replacement worry with 10-year Interferometer, 5-year laser, & 2-year source warranty
Footprint (WxDxH in mm)	500x580x230	550x570x250	Comparable footprint, more value for the iS10

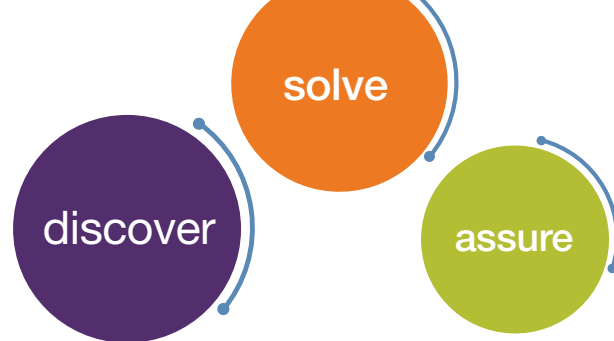

ThermoFisher
SCIENTIFIC

5225 Verona Road • Madison, WI 53711-4495



Trade in your Nicolet 380 today and save over 20%!

Request a quote at thermofisher.com/380CAP