

CD45R (B220) Monoclonal Antibody (RA3-6B2), eFluor 570, eBioscience™

Product Details	
Size	25 µg
Species Reactivity	Human, Mouse
Published Species	Mouse, Human
Host/Isotope	Rat / IgG2a, kappa
Recommended Isotype Control	Rat IgG2a kappa Isotype Control (eBR2a), eFluor 570, eBioscience™
Class	Monoclonal
Type	Antibody
Clone	RA3-6B2
Conjugate	eFluor® 570
Form	Liquid
Concentration	0.2 mg/mL
Purification	Affinity chromatography
Storage buffer	PBS, pH 7.2, with 0.1% gelatin
Contains	0.09% sodium azide
Storage Conditions	4° C, store in dark, DO NOT FREEZE!
RRID	AB_2573598

Applications	Tested	Dilution	Published
Immunohistochemistry (Paraffin) (IHC (P))	✓	1 µg/mL	1 Publication
Immunofluorescence (IF)	✓	Assay-Dependent	10 Publications
Immunohistochemistry (IHC)	-		6 Publications
Immunohistochemistry (Frozen) (IHC (F))	✓	1 µg/mL	2 Publications
Immunocytochemistry (ICC)	✓	Assay-Dependent	

Product Specific Information

Description: The RA3-6B2 monoclonal antibody reacts with exon A-restricted isoform of mouse CD45, a 220 kDa surface molecule. CD45R/B220 epitope is mainly expressed by the B cell lineage from early Pro-B to mature B cells. However, some activated T cells, lymphokine activated killer cells (LAK), NK cell progenitors in the bone marrow, and T cells of the lpr/lpr mutant mouse also express this antigen.

Applications Reported: This RA3-6B2 antibody has been reported for use in microscopy, immunocytochemistry, and immunohistochemical staining of formalin-fixed paraffin embedded or frozen tissue sections.


Applications Tested: This RA3-6B2 antibody has been tested by immunohistochemistry of frozen mouse spleen and can be used

at less than or equal to 1 µg/mL. It is recommended that the antibody be carefully titrated for optimal performance in the assay of interest.

Filter Recommendation: When using this eFluor® 570 antibody conjugate, we recommend a filter that will capture the 570 emission wavelength (for example, Excitation 545/25, 565LP, Emission 605/70). A standard Alexa Fluor® 555 or TRITC filter is acceptable.

Excitation: 555 nm; Emission: 570 nm


Advanced Verification Data

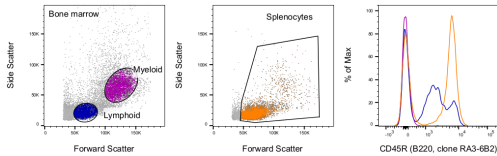

CD45R (B220) Antibody (41-0452-80)

Staining of mouse splenocytes and bone marrow cells. As expected based on known relative expression patterns, CD45R (B220) clone RA3-6B2 stains subsets in both the splenocytes gate and the bone marrow lymphoid gate but not the bone marrow myeloid gate. Details: Balb/c bone marrow cells (left) and splenocytes (middle) were surface stained with CD45R (B220, clone RA3-6B2) followed by staining with 7-AAD. Viable bone marrow cells in the lymphoid (blue histogram) and myeloid (purple histogram) gates and viable splenocytes (orange histogram) were used for analysis. Relative expression validation info.

Product Images For CD45R (B220) Monoclonal Antibody (RA3-6B2), eFluor 570, eBioscience™

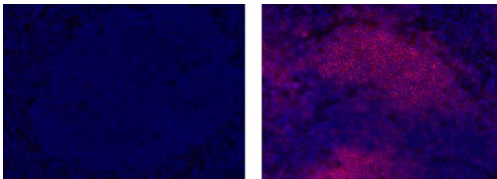

CD45R (B220) Antibody (41-0452-80) in IF

Immunohistochemistry of frozen mouse spleen using 1 µg/mL of Rat IgG2a K Isotype Control eFluor® 570 (left) or 1 µg/mL of Anti-Human/Mouse CD45R (B220) eFluor® 570 (right). Nuclei are stained with DAPI.

View more figures on thermofisher.com

19 References

Immunohistochemistry (Paraffin) (1)

European journal of microbiology and immunology

Anti-inflammatory Effects of the Octapeptide NAP in Human Microbiota-Associated Mice Suffering from Subacute Ileitis.

"Published figure using CD45R (B220) monoclonal antibody (Product # 41-0452-80) in Immunohistochemistry (Paraffin)"

Authors: Escher U, Giladi E, Dunay IR, Bereswill S, Gozes I, Heimesaat MM

Species
Not Applicable

Dilution
Not Cited

Year
2018

Immunofluorescence (10)

The Journal of experimental medicine

Microbial symbionts regulate the primary Ig repertoire.

"Published figure using CD45R (B220) monoclonal antibody (Product # 41-0452-80) in Immunofluorescence"

Authors: Chen Y, Chaudhary N, Yang N, Granato A, Turner JA, Howard SL, Devereaux C, Zuo T, Shrestha A, Goel RR, Neuberger D, Wesemann DR

Species
Not Applicable

Dilution
Not Cited

Year
2018

Immunity

Oxysterol Sensing through the Receptor GPR183 Promotes the Lymphoid-Tissue-Inducing Function of Innate Lymphoid Cells and Colonic Inflammation.

"Published figure using CD45R (B220) monoclonal antibody (Product # 41-0452-80) in Immunofluorescence"

Authors: Emgård J, Kammoun H, García-Cassani B, Chesné J, Parigi SM, Jacob JM, Cheng HW, Evren E, Das S, Czarnewski P, Sleiers N, Melo-Gonzalez F, Kvedaraitė E, Svensson M, Scandella E, Hepworth MR, Huber S, Ludewig B, Peduto L, Villablanca EJ, Veiga-Fernandes H, Pereira JP, Flavell RA, Willinger T

Species
Not Applicable

Dilution
Not Cited

Year
2018

[View more IF references on thermofisher.com](#)

Immunohistochemistry (6)

Scientific reports

Multidrug-resistant *Pseudomonas aeruginosa* aggravates inflammatory responses in murine chronic colitis.

"Published figure using CD45R (B220) monoclonal antibody (Product # 41-0452-80) in Immunohistochemistry"

Authors: von Klitzing E, Ekmekciü I, Kühl AA, Bereswill S, Heimesaat MM

Species
Not Applicable

Dilution
Not Cited

Year
2018

[View more IHC references on thermofisher.com](#)

More applications with references on thermofisher.com

IHC (F) (2)

For Research Use Only. Not for use in diagnostic procedures. Not for resale without express authorization. Products are warranted to operate or perform substantially in conformance with published Product specifications in effect at the time of sale, as set forth in the Production documentation, specifications and/or accompanying package inserts ("Documentation"). No claim of suitability for use in applications regulated by FDA is made. The warranty provided herein is valid only when used by properly trained individuals. Unless otherwise stated in the Documentation, this warranty is limited to one year from date of shipment when the Product is subjected to normal, proper and intended usage. This warranty does not extend to anyone other than the Buyer. Any model or sample furnished to Buyer is merely illustrative of the general type and quality of goods and does not represent that any Product will conform to such model or sample. NO OTHER WARRANTIES, EXPRESS OR IMPLIED, ARE GRANTED INCLUDING WITHOUT LIMITATION, IMPLIED WARRANTIES OF MERCHANTABILITY, FITNESS FOR ANY PARTICULAR PURPOSE, OR NON INFRINGEMENT. BUYER'S EXCLUSIVE REMEDY FOR NON-CONFORMING PRODUCTS DURING THE WARRANTY PERIOD IS LIMITED TO REPAIR, REPLACEMENT OF OR REFUND FOR THE NON-CONFORMING PRODUCT(S) AT SELLER'S SOLE OPTION. THERE IS NO OBLIGATION TO REPAIR, REPLACE OR REFUND FOR PRODUCTS AS THE RESULT OF (I) ACCIDENT, DISASTER OR EVENT OF FORCE MAJEURE, (II) MISUSE, FAULT OR NEGLIGENCE OF OR BY BUYER, (III) USE OF THE PRODUCTS IN A MANNER FOR WHICH THEY WERE NOT DESIGNED, OR (IV) IMPROPER STORAGE AND HANDLING OF THE PRODUCTS. Unless otherwise expressly stated on the Product or in the documentation accompanying the Product, the Product is intended for research only and is not to be used for any other purpose, including without limitation, unauthorized commercial uses, in vitro diagnostic uses, ex vivo or in vivo therapeutic uses, or any type of consumption by or application to human or animals.