

# TRA-1-81 Monoclonal Antibody (TRA-1-81), HRP


Product Details	
Size	100 µL
Species Reactivity	Human
Host/Isotype	Mouse / IgM
Class	Monoclonal
Type	Antibody
Clone	TRA-1-81
Conjugate	HRP
Immunogen	human embryonal carcinoma cell line 2102Ep
Form	Liquid
Concentration	1 mg/mL
Purification	Affinity chromatography - MBP
Storage buffer	proprietary buffer with proprietary stabilizer
Contains	0.07% Kathon
Storage conditions	4° C, do not freeze
RRID	AB_2536710

Applications	Tested Dilution	Publications
Western Blot (WB)	1:250-1:1,000	-

## Product Specific Information

MA1-024-HRP has been successfully used in Western blot applications on human samples.

Product Images For TRA-1-81 Monoclonal Antibody (TRA-1-81), HRP

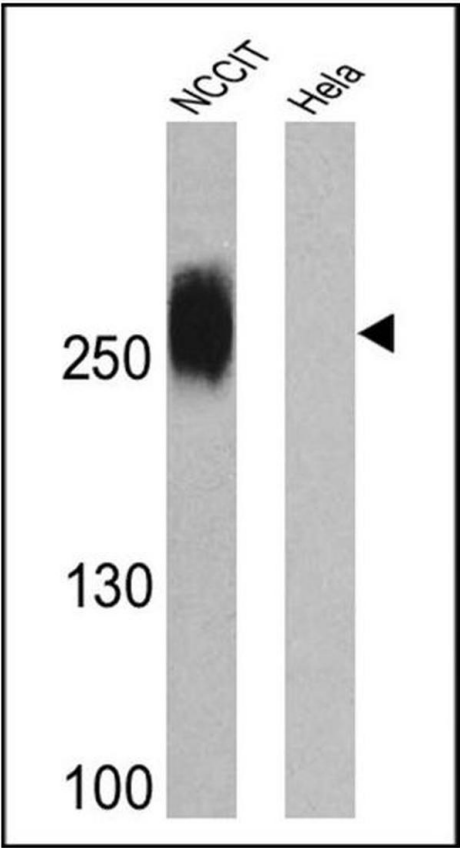

TRA-1-81 Antibody (MA1-024-HRP) in WB

Western blot analysis of TRA-1-81 was performed by loading 50 µg of NCCIT and negative control HeLa cell lysates per well onto an SDS polyacrylamide gel. Proteins were transferred to a PVDF membrane. The membrane was blocked, and probed with an HRP-conjugated TRA-1-81 monoclonal antibody (Product # MA1-024-HRP) at a dilution of 1:1000 overnight at 4C. Chemiluminescent detection was performed using SuperSignal West Dura (Product # 34075).

For Research Use Only. Not for use in diagnostic procedures. Not for resale without express authorization. Products are warranted to operate or perform substantially in conformance with published Product specifications in effect at the time of sale, as set forth in the Production documentation, specifications and/or accompanying package inserts ("Documentation"). No claim of suitability for use in applications regulated by FDA is made. The warranty provided herein is valid only when used by properly trained individuals. Unless otherwise stated in the Documentation, this warranty is limited to one year from date of shipment when the Product is subjected to normal, proper and intended usage. This warranty does not extend to anyone other than the Buyer. Any model or sample furnished to Buyer is merely illustrative of the general type and quality of goods and does not represent that any Product will conform to such model or sample. NO OTHER WARRANTIES, EXPRESS OR IMPLIED, ARE GRANTED INCLUDING WITHOUT LIMITATION, IMPLIED WARRANTIES OF MERCHANTABILITY, FITNESS FOR ANY PARTICULAR PURPOSE, OR NON INFRINGEMENT. BUYER'S EXCLUSIVE REMEDY FOR NON-CONFORMING PRODUCTS DURING THE WARRANTY PERIOD IS LIMITED TO REPAIR, REPLACEMENT OF OR REFUND FOR THE NON-CONFORMING PRODUCT(S) AT SELLER'S SOLE OPTION. THERE IS NO OBLIGATION TO REPAIR, REPLACE OR REFUND FOR PRODUCTS AS THE RESULT OF (i) ACCIDENT, DISASTER OR EVENT OF FORCE MAJEURE, (ii) MISUSE, FAULT OR NEGLIGENCE OF OR BY BUYER, (iii) USE OF THE PRODUCTS IN A MANNER FOR WHICH THEY WERE NOT DESIGNED, OR (iv) IMPROPER STORAGE AND HANDLING OF THE PRODUCTS. Unless otherwise expressly stated on the Product or in the documentation accompanying the Product, the Product is intended for research only and is not to be used for any other purpose, including without limitation, unauthorized commercial uses, in vitro diagnostic uses, ex vivo or in vivo therapeutic uses, or any type of consumption by or application to human or animals.