

LAT Monoclonal Antibody (LAT-01)

Product Details	
Size	100 µg
Species Reactivity	Human
Host/Isotype	Mouse / IgG1
Class	Monoclonal
Type	Antibody
Clone	LAT-01
Conjugate	Unconjugated
Immunogen	Bacterially produced recombinant polypeptide corresponding to the entire cytoplasmic domain of human LAT
Form	Liquid
Concentration	1 mg/mL
Purification	Protein A
Storage buffer	PBS, pH 7.4
Contains	15mM sodium azide
Storage conditions	4° C, do not freeze
RRID	AB_1076434

Applications	Tested Dilution	Publications
Western Blot (WB)	1-2 µg/mL	-
Flow Cytometry (Flow)	1-4 µg/mL	-
Immunoprecipitation (IP)	Assay-dependent	-


Product Specific Information

This antibody will not cross-react with mouse.

Product Images For LAT Monoclonal Antibody (LAT-01)


LAT Antibody (MA1-19307) in WB

Western blot was performed using Anti-LAT Monoclonal Antibody (LAT-01) (Product # MA1-19307) and a 34kDa, 28kDa, 27kDa and 24kDa band corresponding to LAT was observed across in T cell line, Jurkat, and Natural Killer cells, NK-92, but not in B-cells (Raji and Daudi). Membrane enriched extracts (30 µg lysate) of Jurkat (Lane 1), Raji (Lane 2), Daudi (Lane 3), NK-92 (Lane 4) were electrophoresed using NuPAGE™ 12% Bis-Tris Protein Gel (Product # NP0341BOX). Resolved proteins were then transferred onto a Nitrocellulose membrane (Product # IB23001) by iBlot® 2 Dry Blotting System (Product # IB21001). The blot was probed with the primary antibody (1:1250) and detected by chemiluminescence with Goat anti-Mouse IgG (H+L) Superclonal™ Recombinant Secondary Antibody, HRP (Product # A28177,1:8000) using the iBright FL 1000 (Product # A32752). Chemiluminescent detection was performed using Novex® ECL Chemiluminescent Substrate Reagent Kit (Product # WP20005). Linker for T cell activation (LAT) is preferentially expressed in higher levels in T-cells and Natural Killer cells for its development and proliferation. Additional proteolytically cleaved products, reported at several molecular weights >13kDa, are detected in Jurkat and NK-cells in comparison to the B-cell lines tested. [doi:10.3389/fimmu.2018.00115, 10.1042/BJ20121135]

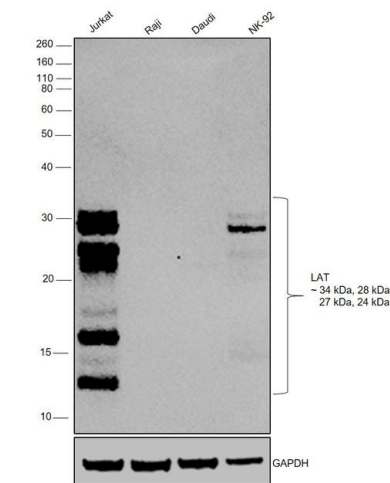


LAT Antibody (MA1-19307) in WB

Western blotting analysis of human LAT using mouse monoclonal antibody LAT-01 in lysates of Jurkat cells (positive) and Raji cells (negative control) under non-reducing and reducing conditions. Nitrocellulose membrane was probed with 2µg /mL of mouse anti-LAT Monoclonal antibody (Product # MA1-19307) followed by IRDye800-conjugated anti-mouse secondary antibody. A specific band was detected for LAT at approximately 38kDa.

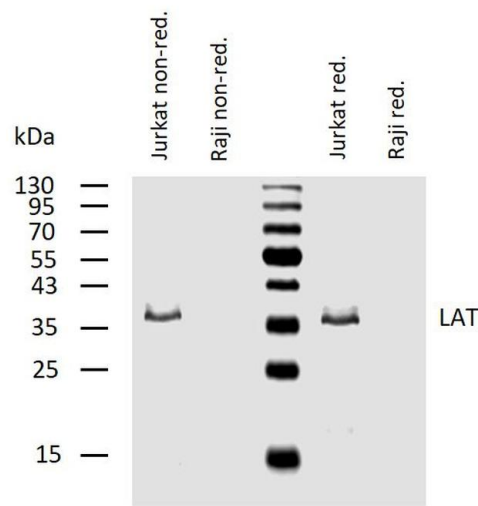

LAT Antibody (MA1-19307) in Flow

Flow cytometry multicolor intracellular staining of human peripheral whole blood stained using anti-LAT (LAT-01) purified Monoclonal antibody (Product # MA1-19307) (concentration in sample 1 µg/mL, GAM APC) and anti-human CD3 (UCHT1) Pacific Blue™ using a dilution of 20 µL reagent/100 µL of peripheral whole blood.

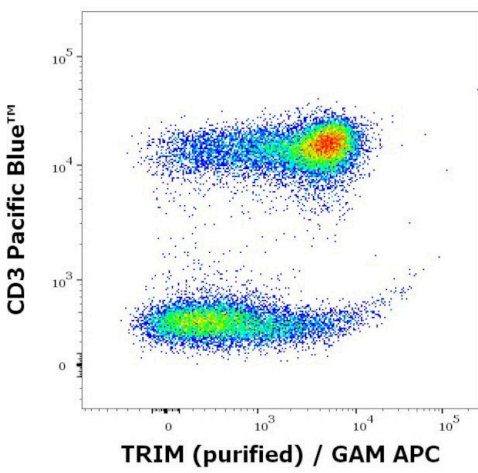

View more figures on thermofisher.com

For Research Use Only. Not for use in diagnostic procedures. Not for resale without express authorization. Products are warranted to operate or perform substantially in conformance with published Product specifications in effect at the time of sale, as set forth in the Production documentation, specifications and/or accompanying package inserts ("Documentation"). No claim of suitability for use in applications regulated by FDA is made. The warranty provided herein is valid only when used by properly trained individuals. Unless otherwise stated in the Documentation, this warranty is limited to one year from date of shipment when the Product is subjected to normal, proper and intended usage. This warranty does not extend to anyone other than the Buyer. Any model or sample furnished to Buyer is merely illustrative of the general type and quality of goods and does not represent that any Product will conform to such model or sample. NO OTHER WARRANTIES, EXPRESS OR IMPLIED, ARE GRANTED INCLUDING WITHOUT LIMITATION, IMPLIED WARRANTIES OF MERCHANTABILITY, FITNESS FOR ANY PARTICULAR PURPOSE, OR NON INFRINGEMENT. BUYER'S EXCLUSIVE REMEDY FOR NON-CONFORMING PRODUCTS DURING THE WARRANTY PERIOD IS LIMITED TO REPAIR, REPLACEMENT OF OR REFUND FOR THE NON-CONFORMING PRODUCT(S) AT SELLER'S SOLE OPTION. THERE IS NO OBLIGATION TO REPAIR, REPLACE OR REFUND FOR PRODUCTS AS THE RESULT OF (I) ACCIDENT, DISASTER OR EVENT OF FORCE MAJEURE, (II) MISUSE, FAULT OR NEGLIGENCE OF OR BY BUYER, (III) USE OF THE PRODUCTS IN A MANNER FOR WHICH THEY WERE NOT DESIGNED, OR (IV) IMPROPER STORAGE AND HANDLING OF THE PRODUCTS. Unless otherwise expressly stated on the Product or in the documentation accompanying the Product, the Product is intended for research only and is not to be used for any other purpose, including without limitation, unauthorized commercial uses, in vitro diagnostic uses, ex vivo or in vivo therapeutic uses, or any type of consumption by or application to human or animals.