

NY-BR-1 Monoclonal Antibody (NY-BR-1 No. 2)

Product Details	
Size	1 mL
Species Reactivity	Human
Published Species	Human
Host/Isotype	Mouse / IgG1, kappa
Class	Monoclonal
Type	Antibody
Clone	NY-BR-1 No. 2
Conjugate	Unconjugated
Immunogen	A 77 aa peptide from human NYBR-1 protein
Form	Liquid
Concentration	0.2 mg/mL
Purification	Protein G
Storage buffer	PBS, pH 7.4, with 0.2% BSA
Contains	0.09% sodium azide
Storage conditions	4° C
RRID	AB_10977217


Applications	Tested Dilution	Publications
Immunohistochemistry (IHC)	-	1 Publication
Immunohistochemistry (Paraffin) (IHC (P))	1:100	-
Immunohistochemistry (Frozen) (IHC (F))	1:100	-

Product Specific Information

MA5-12645 targets NY-BR-1 in IHC (P, F) applications and shows reactivity with Human samples.

The MA5-12645 immunogen is a 77 aa peptide from human NYBR-1 protein.

Product Images For NY-BR-1 Monoclonal Antibody (NY-BR-1 No. 2)

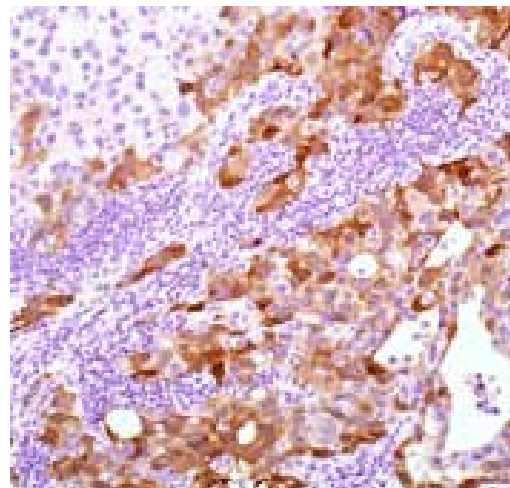

NY-BR-1 Antibody (MA5-12645) in IHC (P)
Formalin-fixed paraffin-embedded metastatic breast ca to lymph node stained with NY-BR-1 antibody using peroxidase conjugate and DAB chromogen. Note: cytoplasmic and occasional nuclear staining

1 Reference

Immunohistochemistry (1)

American journal of clinical pathology		Year
NY-BR-1 and PAX8 immunoreactivity in breast, gynecologic tract, and other CK7+ carcinomas: potential use for determining site of origin.		2011
"MA5-12645 was used in immunohistochemistry to study NY-BR-1 and PAX8 immunoreactivity in CK7+ carcinomas and utility in determining the site of origin"		Species
Authors: Woodard AH,Yu J,Dabbs DJ,Beriwal S,Florea AV,Elishaev E,Davison JM,Krasinskas AM,Bhargava R		Human

For Research Use Only. Not for use in diagnostic procedures. Not for resale without express authorization. Products are warranted to operate or perform substantially in conformance with published Product specifications in effect at the time of sale, as set forth in the Production documentation, specifications and/or accompanying package inserts ("Documentation"). No claim of suitability for use in applications regulated by FDA is made. The warranty provided herein is valid only when used by properly trained individuals. Unless otherwise stated in the Documentation, this warranty is limited to one year from date of shipment when the Product is subjected to normal, proper and intended usage. This warranty does not extend to anyone other than the Buyer. Any model or sample furnished to Buyer is merely illustrative of the general type and quality of goods and does not represent that any Product will conform to such model or sample. NO OTHER WARRANTIES, EXPRESS OR IMPLIED, ARE GRANTED INCLUDING WITHOUT LIMITATION, IMPLIED WARRANTIES OF MERCHANTABILITY, FITNESS FOR ANY PARTICULAR PURPOSE, OR NON INFRINGEMENT. BUYER'S EXCLUSIVE REMEDY FOR NON-CONFORMING PRODUCTS DURING THE WARRANTY PERIOD IS LIMITED TO REPAIR, REPLACEMENT OF OR REFUND FOR THE NON-CONFORMING PRODUCT(S) AT SELLER'S SOLE OPTION. THERE IS NO OBLIGATION TO REPAIR, REPLACE OR REFUND FOR PRODUCTS AS THE RESULT OF (i) ACCIDENT, DISASTER OR EVENT OF FORCE MAJEURE, (ii) MISUSE, FAULT OR NEGLIGENCE OF OR BY BUYER, (iii) USE OF THE PRODUCTS IN A MANNER FOR WHICH THEY WERE NOT DESIGNED, OR (iv) IMPROPER STORAGE AND HANDLING OF THE PRODUCTS. Unless otherwise expressly stated on the Product or in the documentation accompanying the Product, the Product is intended for research only and is not to be used for any other purpose, including without limitation, unauthorized commercial uses, in vitro diagnostic uses, ex vivo or in vivo therapeutic uses, or any type of consumption by or application to human or animals.