


gamma Tubulin Monoclonal Antibody (TU-30), Alexa Fluor™ 647

Product Details	
Size	100 µg
Species Reactivity	Bovine, Chicken, Human, Mouse, Plant, Pig, Protozoa, Rat
Host/Isotype	Mouse / IgG1
Class	Monoclonal
Type	Antibody
Clone	TU-30
Conjugate	Alexa Fluor™ 647
Excitation/Emission Max	650/671 nm
Immunogen	C-terminal peptide of gamma-tubulin counjugated to KLH
Form	Liquid
Concentration	1 mg/mL
Purification	Size-exclusion chromatography
Storage buffer	PBS, pH 7.4
Contains	15mM sodium azide
Storage conditions	4° C, store in dark, DO NOT FREEZE!
RRID	AB_2913074

Applications	Tested Dilution	Publications
Western Blot (WB)	Assay-dependent	-
Immunocytochemistry (ICC/IF)	Assay-dependent	-
Flow Cytometry (Flow)	1-5 µg/mL	-

Product Images For gamma Tubulin Monoclonal Antibody (TU-30), Alexa Fluor™ 647

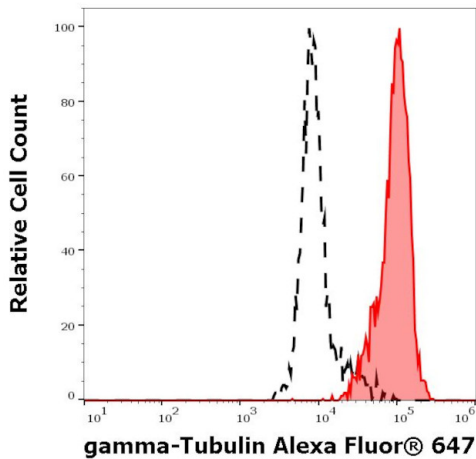

gamma Tubulin Antibody (MA5-44142) in Flow
Separation of HeLa cells stained using anti-gamma-Tubulin (TU-30) Alexa Fluor® 647 Monoclonal antibody (Product # MA5-44142), concentration in sample 5 µg/mL (red-filled) from HeLa cells stained using mouse IgG1 isotype control (MOPC-21) Alexa Fluor® 647 antibody (concentration in sample 5 µg/mL, same as anti-gamma-Tubulin Alexa Fluor® 647 concentration, black-dashed) in flow cytometry analysis (intracellular staining) of HeLa cell suspension.

For Research Use Only. Not for use in diagnostic procedures. Not for resale without express authorization. Products are warranted to operate or perform substantially in conformance with published Product specifications in effect at the time of sale, as set forth in the Production documentation, specifications and/or accompanying package inserts ("Documentation"). No claim of suitability for use in applications regulated by FDA is made. The warranty provided herein is valid only when used by properly trained individuals. Unless otherwise stated in the Documentation, this warranty is limited to one year from date of shipment when the Product is subjected to normal, proper and intended usage. This warranty does not extend to anyone other than the Buyer. Any model or sample furnished to Buyer is merely illustrative of the general type and quality of goods and does not represent that any Product will conform to such model or sample. NO OTHER WARRANTIES, EXPRESS OR IMPLIED, ARE GRANTED INCLUDING WITHOUT LIMITATION, IMPLIED WARRANTIES OF MERCHANTABILITY, FITNESS FOR ANY PARTICULAR PURPOSE, OR NON INFRINGEMENT. BUYER'S EXCLUSIVE REMEDY FOR NON-CONFORMING PRODUCTS DURING THE WARRANTY PERIOD IS LIMITED TO REPAIR, REPLACEMENT OF OR REFUND FOR THE NON-CONFORMING PRODUCT(S) AT SELLER'S SOLE OPTION. THERE IS NO OBLIGATION TO REPAIR, REPLACE OR REFUND FOR PRODUCTS AS THE RESULT OF (I) ACCIDENT, DISASTER OR EVENT OF FORCE MAJEURE, (II) MISUSE, FAULT OR NEGLIGENCE OF OR BY BUYER, (III) USE OF THE PRODUCTS IN A MANNER FOR WHICH THEY WERE NOT DESIGNED, OR (IV) IMPROPER STORAGE AND HANDLING OF THE PRODUCTS. Unless otherwise expressly stated on the Product or in the documentation accompanying the Product, the Product is intended for research only and is not to be used for any other purpose, including without limitation, unauthorized commercial uses, in vitro diagnostic uses, ex vivo or in vivo therapeutic uses, or any type of consumption by or application to human or animals.