

Zap-70 Monoclonal Antibody (1E7.2), Pacific Blue™


Product Details	
Size	500 µL
Species Reactivity	Human, Mouse
Host/Isotype	Mouse / IgG1
Class	Monoclonal
Type	Antibody
Clone	1E7.2
Conjugate	Pacific Blue™
Excitation/Emission Max	404/455 nm
Immunogen	GST-fusion protein of Human ZAP70, amino acids 282-307
Form	Liquid
Purification	Affinity chromatography
Storage buffer	PBS with 4mg/mL BSA
Contains	0.1% sodium azide
Storage conditions	4° C, store in dark
RRID	AB_2539778

Applications	Tested Dilution	Publications
Flow Cytometry (Flow)	Assay-Dependent	-

Product Specific Information

Our Pacific Blue™ dye is optimally excited by the violet laser and conjugates of this dye are strongly fluorescent even at neutral pH. Pacific Blue™ and Pacific Orange™ dye conjugates can be simultaneously excited at 405 nm and emit at 455 nm and 551 nm, respectively, facilitating two-color analysis.

Product Images For Zap-70 Monoclonal Antibody (1E7.2), Pacific Blue™

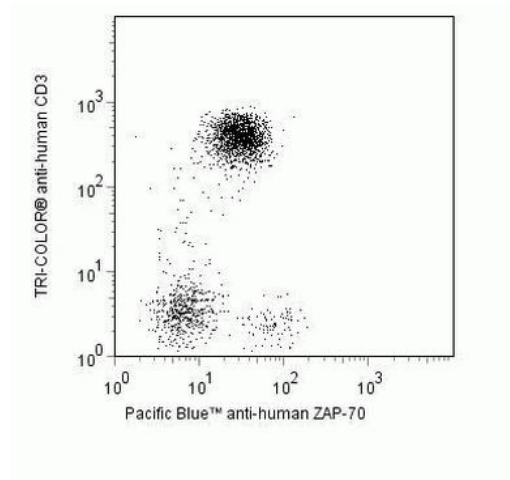

Zap-70 Antibody (MHZAP7028) in Flow
Human lymphocytes stained with Pacific Blue™ anti-human ZAP-70 (Product # MHZAP7028) and TRI-COLOR® anti-human CD3 (Product # MHCD0305).

For Research Use Only. Not for use in diagnostic procedures. Not for resale without express authorization. Products are warranted to operate or perform substantially in conformance with published Product specifications in effect at the time of sale, as set forth in the Production documentation, specifications and/or accompanying package inserts ("Documentation"). No claim of suitability for use in applications regulated by FDA is made. The warranty provided herein is valid only when used by properly trained individuals. Unless otherwise stated in the Documentation, this warranty is limited to one year from date of shipment when the Product is subjected to normal, proper and intended usage. This warranty does not extend to anyone other than the Buyer. Any model or sample furnished to Buyer is merely illustrative of the general type and quality of goods and does not represent that any Product will conform to such model or sample. NO OTHER WARRANTIES, EXPRESS OR IMPLIED, ARE GRANTED INCLUDING WITHOUT LIMITATION, IMPLIED WARRANTIES OF MERCHANTABILITY, FITNESS FOR ANY PARTICULAR PURPOSE, OR NON INFRINGEMENT. BUYER'S EXCLUSIVE REMEDY FOR NON-CONFORMING PRODUCTS DURING THE WARRANTY PERIOD IS LIMITED TO REPAIR, REPLACEMENT OF OR REFUND FOR THE NON-CONFORMING PRODUCT(S) AT SELLER'S SOLE OPTION. THERE IS NO OBLIGATION TO REPAIR, REPLACE OR REFUND FOR PRODUCTS AS THE RESULT OF (i) ACCIDENT, DISASTER OR EVENT OF FORCE MAJEURE, (ii) MISUSE, FAULT OR NEGLIGENCE OF OR BY BUYER, (iii) USE OF THE PRODUCTS IN A MANNER FOR WHICH THEY WERE NOT DESIGNED, OR (iv) IMPROPER STORAGE AND HANDLING OF THE PRODUCTS. Unless otherwise expressly stated on the Product or in the documentation accompanying the Product, the Product is intended for research only and is not to be used for any other purpose, including without limitation, unauthorized commercial uses, in vitro diagnostic uses, ex vivo or in vivo therapeutic uses, or any type of consumption by or application to human or animals.